


ProGuard® 15

107359 ProGuard 15 w/107187 Kit & Front Mount Squeegee

\$949

Power and versatility are combined with innovation in the ProGuard 15 Wet/Dry Vacuum. The patented variable wheel pattern allows for increased maneuverability and improved productivity while offering the performance, filtration and durability you expect from a ProTeam vacuum.

**Shown without Front Mount Squeegee.*

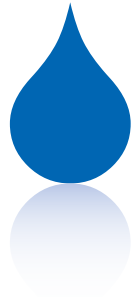

Specifications

Motor:	1380 W/9.5 A
Airflow:	105 CFM
Static Lift:	95"
Tank Size:	15 gallon / 57.0 L
Weight:	68 lbs./31 kg
Decibel:	69 dBA
ProGuard Wet Filter:	Polypropylene Screen
Fine Dust Cartridge Filter:	1276 sq. in.
Power Cord:	50', 14 AWG

Standard Configuration

10' Vacuum Hose
Two-Piece Wand
Nylon Floor Tool
Squeegee Tool
Crevice Tool
Dust Brush

Warranty

3 years parts, labor and motor on vacuum
Limited lifetime on molded body parts


OPTIONAL CONFIGURATIONS

107130	ProGuard 15 w/ Wet/Dry Tool Kit (107187) (no squeegee)	\$759.00
107185	Front Mount Squeegee	198.45

RECOMMENDED APPLICATIONS:

- Retail
- Emergency / Flood Cleanup
- Hard Floor Refinishing
- Manufacturing

PROGUARD 15/20 PARTS

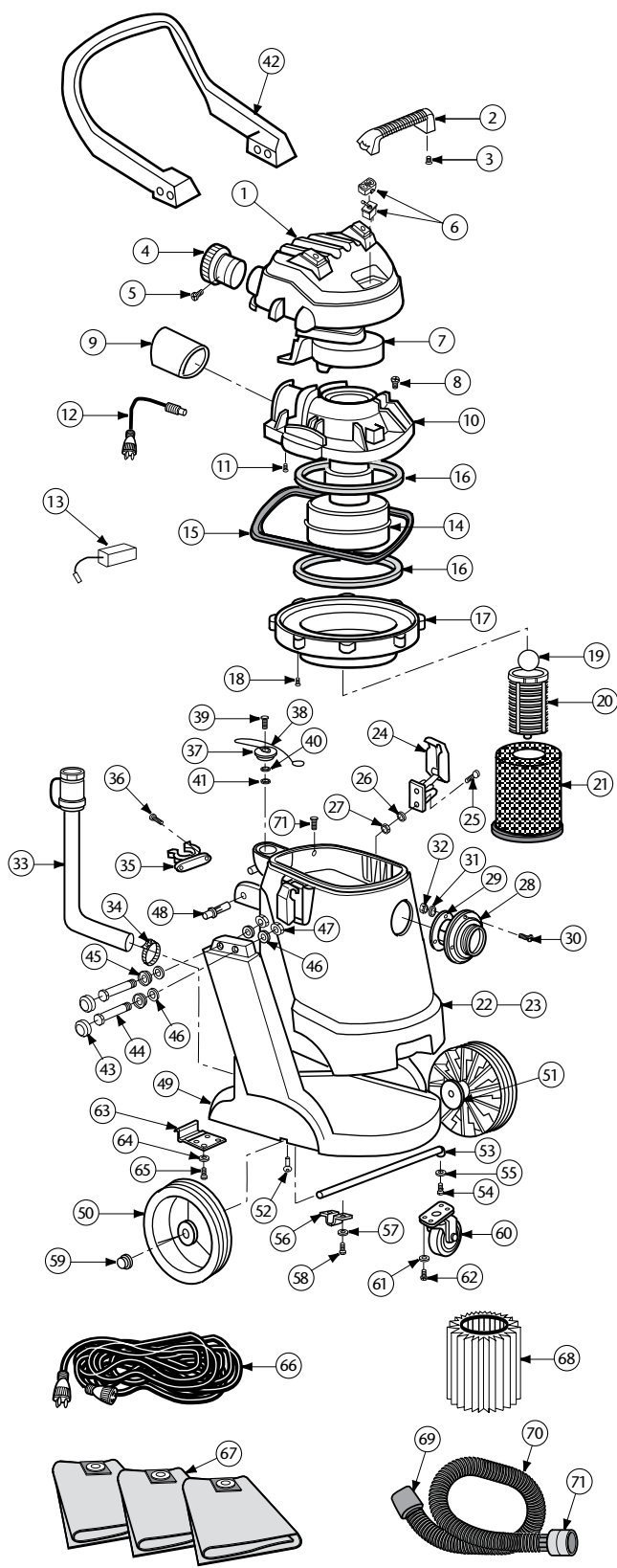

No.	Product Name	Qty	List Price
1	510097 Motor Cover Assembly (ProGuard 15 only)	1 ea.	\$ 11.66
	510104 Motor Cover Assembly (ProGuard 20 only)	1 ea.	18.95
2	830565-2 Handle Motor Cover	1 ea.	2.31
3	820563-4 Screw Type AB #10 x 3/4"	1 ea.	.05
4	833600 Diffuser Assembly	1 ea.	3.83
5	820563-4 Screw Type AB #10 x 3/4"	1 ea.	.05
6	510127 Switch Assembly	1 ea.	1.84
7	831651 Motor Exhaust Duct	1 ea.	6.04
8	826453-2 Screw 10-32 X 3/4"	1 ea.	.16
9	830609 Exhaust Foam Pad	1 ea.	1.47
10	831653-3 Lid	1 ea.	11.13
11	820563-4 Screw Type AB #10 x 3/4"	1 ea.	.05
12	833417 Power Cord Assembly	1 ea.	21.74
13	822374-8 Carbon Brush Set	1 set	4.88
14	831567 Motor Assembly Complete	1 ea.	83.21
15	833518 Gasket Lid	1 ea.	8.93
16	827415 Gasket Motor	1 ea.	4.36
17	831659 Collector Assembly with Foam	1 ea.	9.19
18	820563-4 Screw Type AB #10 x 3/4"	1 ea.	.05
19	833778 Ball Float	1 ea.	1.21
20	830101-1 Filter Cage	1 ea.	2.73
21	107177 Wet Filter	1 ea.	25.15
22	833603 Tank, 20 Gallon (ProGuard 20 only)	1 ea.	183.23
23	833602 Tank, 15 Gallon (ProGuard 15 only)	1 ea.	166.43
24	833424-1 Drum Latch	1 ea.	4.94
25	833492-1 Screw 10-32 X 3/4"	1 ea.	1.00
26	833493 Washer (13/64 ID) #10	1 ea.	.05
27	161255-8 Nut Lock #10	1 ea.	.32
28	833425 Tank Inlet Adapter	1 ea.	2.21
29	833426 Gasket Inlet Adapter	1 ea.	.89
30	833492 Screw 10-32 X 1 1/4"	1 ea.	.37
31	833493 Washer (13/64 ID) #10	1 ea.	.05
32	161255-8 Nut Lock #10	1 ea.	.32
33	833451 Hose Drain Assembly 30" (includes #34)	1 ea.	22.00
34	833452 Hose Clamp	1 ea.	3.41
35	826881 Hose Clip	1 ea.	1.10
36	808872-2 Screw 10-32 X 1 1/4"	1 ea.	.07
37	833449 Cap Rubber Drum Pour Spout	1 ea.	4.36
38	833450 Pour Spout Cable Lanyard	1 ea.	3.89
39	833492 Screw 10-32 X 1 1/4"	1 ea.	.37
40	833493 Washer (13/64 ID) #10	1 ea.	.05
	833492-1 Screw 10-32 x 3/4" (not pictured)	1 ea.	1.00
41	161255-8 Nut Lock #10	1 ea.	.32
42	833465 Handle, Cart Base	1 ea.	60.85
43	100371 Cap	1 ea.	.68
44	832397-1 Screw Hex 3/8-16 X 3 3/4"	1 ea.	4.41
45	833779 Cap Retainer	1 ea.	.47
46	805557-1 Washer 13/32 ID	1 ea.	.05
47	161255-2 Nut Lock 3/8-16	1 ea.	.16
48	833454 Bushing, Drum Hinge	1 ea.	1.26
49	833456 Base, Cart	1 ea.	179.03
50	833459 Wheel 10"	1 ea.	13.60
51	833460 Wheel Spacer	1 ea.	.58
52	833662 Thumb Screw	1 ea.	.79
53	831024-3 Axle	1 ea.	4.52
54	805466-3 Screw Hex HD 5/16-18 X 5/8"	1 ea.	.26
55	140755-12 Lock Washer Ext 5/16"	1 ea.	.05
56	833461 Axle Bracket	1 ea.	1.63
57	140755-12 Lock Washer Ext 5/16"	1 ea.	.05
58	805466-3 Screw Hex HD 5/16-18 X 5/8"	1 ea.	.26
59	813836-1 Nut Washer Cap	1 ea.	.53
60	833462 Caster 4" w/Bearings	1 ea.	16.85
61	140755-12 Lock Washer Ext 5/16"	1 ea.	.05
62	805466-3 Screw Hex HD 5/16-18 X 5/8"	1 ea.	.26
63	833463 Plate Pedal Lock	1 ea.	6.67
64	140755-12 Lock Washer Ext 5/16"	1 ea.	.05
65	805466-3 Screw Hex HD 5/16-18 X 5/8"	1 ea.	.26
66	833432 50' Extension Cord	1 ea.	60.64
67	107180 Intercept Micro Filter	3/pk	35.34
68	107175 Qwik Lock Fine Dust Filter	1 ea.	25.15
69	831577 Swivel Hose Cuff 1 1/2"	1 ea.	2.42
70	107198 Hose Assembly	1 ea.	41.84
71	833587 Locking Ring Cuff	1 ea.	8.03