

ProGuard® 20

107360 ProGuard 20 w/107187 Kit & Front Mount Squeegee
\$999

The ProGuard 20 Wet/Dry Vacuum delivers high power, performance and durability and include thoughtful features that make it easier and more convenient to use. This unit can help cleaning professionals respond quickly to any challenge big or small. Optional front mount squeegee system saves time, money and energy when stripping floors. Patented wheel configuration allows for increased maneuverability.



Specifications

Motor:	1380 W/9.5 A
Airflow:	105 CFM
Static Lift:	95"
Tank Size:	20 gallon / 76.0 L
Weight:	70 lbs./32 kg
Decibel:	69 dBA
ProGuard Wet Filter:	Polypropylene Screen
Fine Dust Cartridge Filter:	1276 sq. in.
Power Cord:	50', 14 AWG

Standard Configuration

10' Vacuum Hose
Two-Piece Wand
Nylon Floor Tool
Squeegee Tool
Crevice Tool
Dust Brush

Warranty

3 years parts, labor and motor on vacuum
Limited lifetime on molded body parts


OPTIONAL CONFIGURATIONS

107131	ProGuard 20 w/Wet/Dry Tool Kit (107187) (no squeegee)	\$809.00
107185	Front Mount Squeegee	198.45

RECOMMENDED APPLICATIONS:

- Retail
- Emergency / Flood Cleanup
- Hard Floor Refinishing
- Manufacturing

PROGUARD 15/20 PARTS

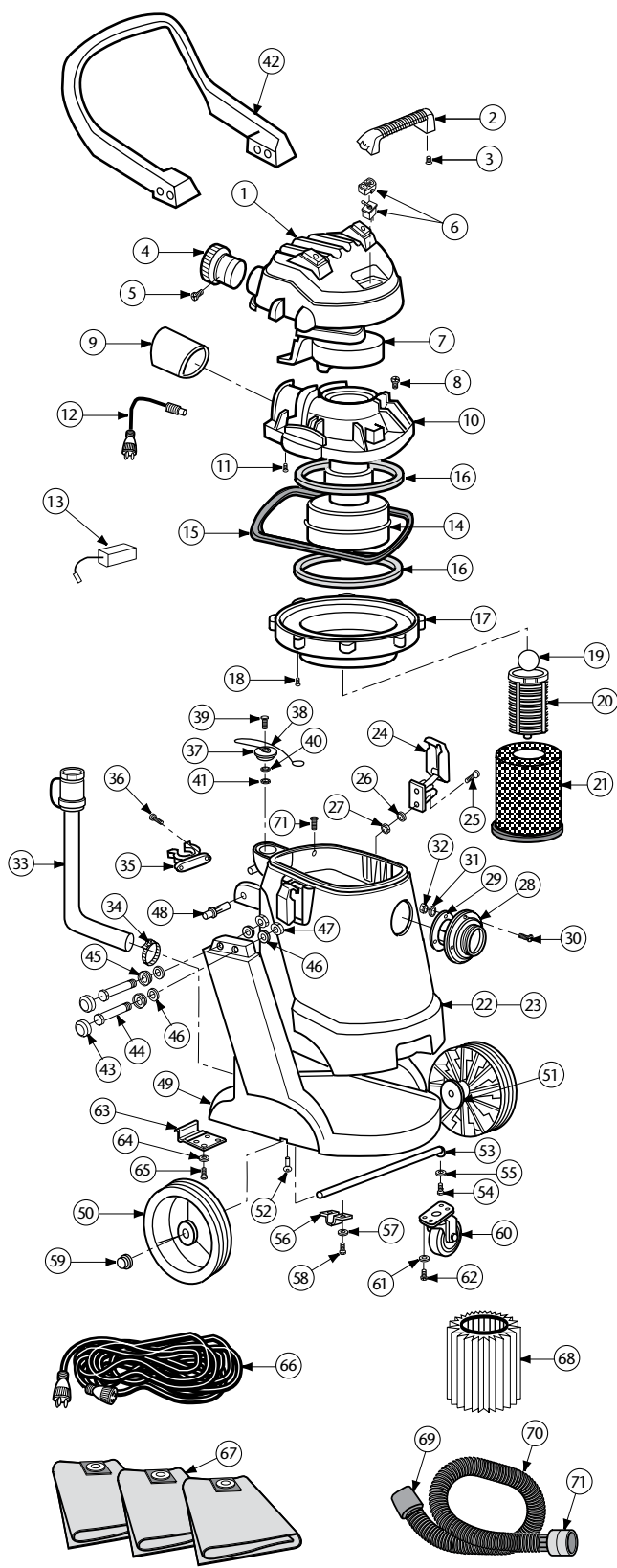

No.	Product Name	Qty	List Price
1	510097 Motor Cover Assembly (ProGuard 15 only)	1 ea.	\$ 11.66
	510104 Motor Cover Assembly (ProGuard 20 only)	1 ea.	18.95
2	830565-2 Handle Motor Cover	1 ea.	2.31
3	820563-4 Screw Type AB #10 x 3/4"	1 ea.	.05
4	833600 Diffuser Assembly	1 ea.	3.83
5	820563-4 Screw Type AB #10 x 3/4"	1 ea.	.05
6	510127 Switch Assembly	1 ea.	1.84
7	831651 Motor Exhaust Duct	1 ea.	6.04
8	826453-2 Screw 10-32 X 3/4"	1 ea.	.16
9	830609 Exhaust Foam Pad	1 ea.	1.47
10	831653-3 Lid	1 ea.	11.13
11	820563-4 Screw Type AB #10 x 3/4"	1 ea.	.05
12	833417 Power Cord Assembly	1 ea.	21.74
13	822374-8 Carbon Brush Set	1 set	4.88
14	831567 Motor Assembly Complete	1 ea.	83.21
15	833518 Gasket Lid	1 ea.	8.93
16	827415 Gasket Motor	1 ea.	4.36
17	831659 Collector Assembly with Foam	1 ea.	9.19
18	820563-4 Screw Type AB #10 x 3/4"	1 ea.	.05
19	833778 Ball Float	1 ea.	1.21
20	830101-1 Filter Cage	1 ea.	2.73
21	107177 Wet Filter	1 ea.	25.15
22	833603 Tank, 20 Gallon (ProGuard 20 only)	1 ea.	183.23
23	833602 Tank, 15 Gallon (ProGuard 15 only)	1 ea.	166.43
24	833424-1 Drum Latch	1 ea.	4.94
25	833492-1 Screw 10-32 X 3/4"	1 ea.	1.00
26	833493 Washer (13/64 ID) #10	1 ea.	.05
27	161255-8 Nut Lock #10	1 ea.	.32
28	833425 Tank Inlet Adapter	1 ea.	2.21
29	833426 Gasket Inlet Adapter	1 ea.	.89
30	833492 Screw 10-32 X 1 1/4"	1 ea.	.37
31	833493 Washer (13/64 ID) #10	1 ea.	.05
32	161255-8 Nut Lock #10	1 ea.	.32
33	833451 Hose Drain Assembly 30" (includes #34)	1 ea.	22.00
34	833452 Hose Clamp	1 ea.	3.41
35	826881 Hose Clip	1 ea.	1.10
36	808872-2 Screw 10-32 X 1 1/4"	1 ea.	.07
37	833449 Cap Rubber Drum Pour Spout	1 ea.	4.36
38	833450 Pour Spout Cable Lanyard	1 ea.	3.89
39	833492 Screw 10-32 X 1 1/4"	1 ea.	.37
40	833493 Washer (13/64 ID) #10	1 ea.	.05
	833492-1 Screw 10-32 x 3/4" (not pictured)	1 ea.	1.00
41	161255-8 Nut Lock #10	1 ea.	.32
42	833465 Handle, Cart Base	1 ea.	60.85
43	100371 Cap	1 ea.	.68
44	832397-1 Screw Hex 3/8-16 X 3 3/4"	1 ea.	4.41
45	833779 Cap Retainer	1 ea.	.47
46	805557-1 Washer 13/32 ID	1 ea.	.05
47	161255-2 Nut Lock 3/8-16	1 ea.	.16
48	833454 Bushing, Drum Hinge	1 ea.	1.26
49	833456 Base, Cart	1 ea.	179.03
50	833459 Wheel 10"	1 ea.	13.60
51	833460 Wheel Spacer	1 ea.	.58
52	833662 Thumb Screw	1 ea.	.79
53	831024-3 Axle	1 ea.	4.52
54	805466-3 Screw Hex HD 5/16-18 X 5/8"	1 ea.	.26
55	140755-12 Lock Washer Ext 5/16"	1 ea.	.05
56	833461 Axle Bracket	1 ea.	1.63
57	140755-12 Lock Washer Ext 5/16"	1 ea.	.05
58	805466-3 Screw Hex HD 5/16-18 X 5/8"	1 ea.	.26
59	813836-1 Nut Washer Cap	1 ea.	.53
60	833462 Caster 4" w/Bearings	1 ea.	16.85
61	140755-12 Lock Washer Ext 5/16"	1 ea.	.05
62	805466-3 Screw Hex HD 5/16-18 X 5/8"	1 ea.	.26
63	833463 Plate Pedal Lock	1 ea.	6.67
64	140755-12 Lock Washer Ext 5/16"	1 ea.	.05
65	805466-3 Screw Hex HD 5/16-18 X 5/8"	1 ea.	.26
66	833432 50' Extension Cord	1 ea.	60.64
67	107180 Intercept Micro Filter	3/pk	35.34
68	107175 Qwik Lock Fine Dust Filter	1 ea.	25.15
69	831577 Swivel Hose Cuff 1 1/2"	1 ea.	2.42
70	107198 Hose Assembly	1 ea.	41.84
71	833587 Locking Ring Cuff	1 ea.	8.03