



# PROFORCE 1500 HEPA PARTS

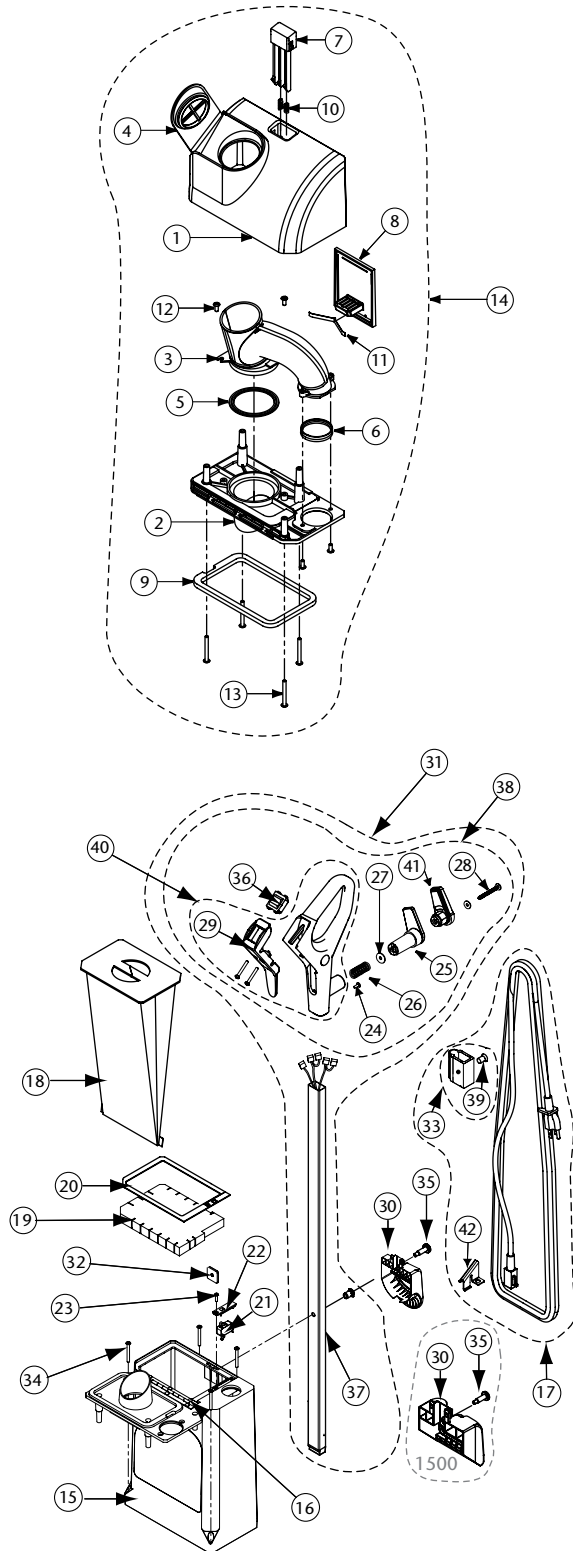

No.	Product Name	Qty	List Price
1	104569 Cover, Bag Housing, Grey	1 ea.	\$17.37
2	104570 Plate, Bag Cover Nozzle	1 ea.	5.79
3	104571 Duct, Crossover, Bag Cover	1 ea.	8.28
4	104574 Plug, Access Port	1 ea.	3.48
5	104575 Seal, Crossover Duct/Bag Cover Nozzle Plate, Lower	1 ea.	2.32
6	104576 Seal, Crossover Duct, Inlet	1 ea.	2.32
7	104232 Latch, Release, Bag Cover	1 ea.	4.63
8	104243 Flex Plate, Bag Cover Latch	1 ea.	2.55
9	104241 Seal, Gasket, Bag Cover	1 ea.	2.55
10	104233 Spring, Release Button, F/Bag Cover Latch	2/pk	2.32
11	104242 Spring, Bag Cover Latch	1 ea.	3.48
12	104577 Screw, Phillips, 4.2mm x 9.5mm	4/pk	2.27
13	104493 Screw, Phillips, 4mm x 38mm	4/pk	4.25
14	105491 Filter Cover Kit, w/Riveted Hinge and 6 Rivets (includes: #1-13)	1 kit	40.75
15	104739 1500 Bag Housing Assembly, Grey, w/Riveted Hinge and Decal Includes Bag Cover Nozzle Plate	1 ea.	41.67
	107284 1500 HEPA Bag Housing Assembly, Grey, w/Riveted Hinge and Decal Includes Bag Cover Nozzle Plate	1 ea.	41.67
16	104491 Rivet F/Bag Housing Assembly	6/pk	3.48
17	104284 Cord, Power Clasp, 50' Yellow (includes: #33, 42)	1 ea.	36.73
18	103483 Intercept Micro Filter	10/pk	11.21
19	104281 Filter, Motor Intake	1 ea.	3.03
20	104738 Seal, Gasket, Bag Housing	1 ea.	2.55
21	104283 Switch, Filter, Lock-Out	1 ea.	10.83
22	104282 Cover, Switch, Filter Lock-out	1 ea.	2.55
23	105075 Screw, Phillips, 2.9mm x 13mm, F/Switch Cover	1 ea.	4.14
24	104509 Screw, Phillips, F/Handle Assembly 4mm x 10mm x .07 Pitch	1 ea.	2.32
25	104268 Bracket, Cord Wrap	1 ea.	4.63
26	104269 Spring, Compression, Cord Wrap Bracket	1 ea.	2.55
27	104270 Washer, Compression Spring, Cord Wrap Bracket	1 ea.	1.16
28	104271 Screw, Cord Wrap, 4mm x 35mm Phillips Round Head	1 ea.	2.32
29	106740 Handle Bezel w/Screws (new style)	1 kit	8.13
30	107289 1500 HEPA Handle, Carry	1 ea.	5.09
	104741 1500 Handle, Carry	1 ea.	5.09
31	106615 Handle, Tube Assembly Complete (includes: #37, 38)	1 kit	63.03
32	104259 Plate, Handle Nut	1 ea.	1.28
33	105091 Clasp, Strain Relief Kit w/Fastener (includes:#39)	1 ea.	6.37
34	104493 Screw, Phillips, 4.2mm x 38mm	4/pk	4.25
35	104266 Screw, Handle Assembly	1 ea.	1.42
36	105147 Switch, Rocker, On/Off	1 ea.	13.89
37	104264 Bushing, Handle Tube	1 ea.	1.28
38	106614 Handle Kit (includes: #25, 26, 27, 28, 29, 30, 36, 40, 41)	1 kit	41.67
39	105320 Ratchet Fastener	1 ea.	4.97
40	107073 Handle Bezel Assembly	1 ea.	23.15
41	107093 Impact Bumper	1 ea.	1.04
42	107203 Cord Retention Clip	1 ea.	.83

For shaded areas refer to page 44

# PROFORCE 1500 HEPA PARTS

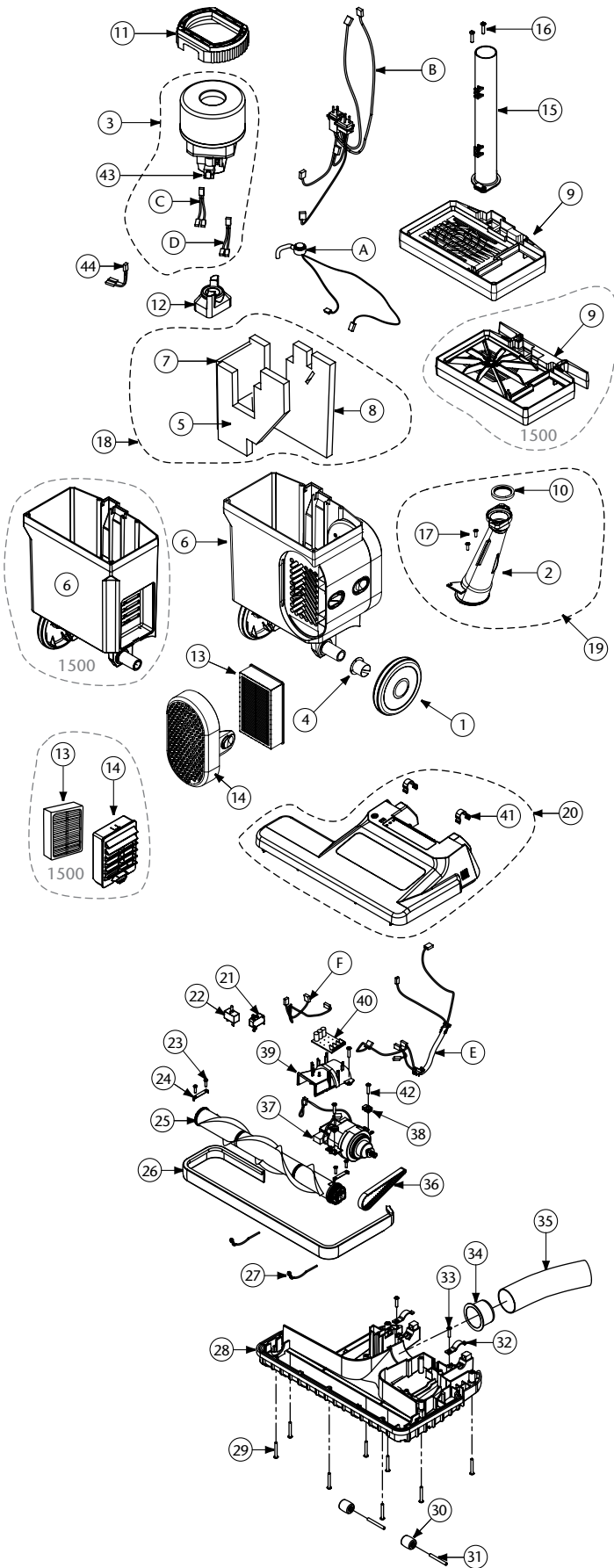

No.	Product Name	Qty	List Price
1	104306 Wheel, Rear	2/pk	\$12.74
2	104250 Air Duct	1 ea.	10.83
3	104957 Motor Assembly Kit w/Jumpers (includes: C, D)	1 ea.	76.41
4	104504 Bearing, Pivot	2/pk	3.48
5	103532 Foam, Sound, Motor Housing Front Panel	1 ea.	5.42
6	104536 1500 Motor Housing, Charcoal	1 ea.	36.17
	107257 1500 HEPA Motor Housing, Charcoal	1 ea.	36.17
7	103533 Foam, Sound, Motor Housing Left Panel	1 ea.	3.18
8	103531 Foam, Sound, Motor Housing Rear Panel	1 ea.	7.64
9	104245 1500 Bulkhead, Dark Grey	1 ea.	15.36
	107255 1500 HEPA Bulkhead, Dark Grey	1 ea.	15.36
10	104253 Seal, Lower Air Duct , Nitrile	1 ea.	1.28
11	104249 Motor Mount, Upper Nitrile	1 ea.	10.83
12	104247 Motor Mount, Lower Nitrile	1 ea.	6.37
13	107005 1500 HEPA Filter, Exhaust, HEPA Media	1 ea.	5.78
	105136 Filter, Exhaust, HEPA Media	1 ea.	6.95
14	107258 1500 HEPA Cover, Filter Cartridge, Charcoal	1 ea.	5.22
	104246 1500/1200 Cover, Filter Cartridge, Charcoal	1 ea.	5.22
15	104578 Air Duct, Upper ProForce 1500	1 ea.	6.95
16	104209 Screw, Phillips, 4mm x 12mm, F/Upper Air Duct	2/pk	2.76
17	104267 Screw, Phillips, 4mm x 12mm, F/Lower Air Duct	2/pk	4.25
18	105488 Motor Housing Sound Filter Kit (includes: #5, 7, 8)	1 kit	15.28
19	105489 Air Duct Kit (includes: #2, 10, 17)	1 kit	11.47
20	107282 1500 HEPA Power Nozzle Cover w/Detent Springs & Decal	1 ea.	31.45
	104494 1500 Power Nozzle Cover w/Detent Springs & Decal	1 ea.	31.45
21	104279 Switch, Safety, Power Nozzle Lockout	1 ea.	13.73
22	104212 Circuit Breaker	1 ea.	17.51
23	104496 Screw, Phillips, 2.9mm x 13mm, F/Brush Retainer	4/pk	5.30
24	104499 Retainer, Brush Roll	2/pk	2.55
25	104216 Brush Roll, Power Nozzle, 14"	1 ea.	30.35
26	104218 Bumper, Power Nozzle, Vinyl	1 ea.	6.95
27	104500 Brace, Formed Wire, F/Power Nozzle Base	2/pk	2.55
28	104221 Baseplate, Power Nozzle	1 ea.	45.80
29	104497 Screw, Phillips, 4mm x 35mm F/Base Cover	8/pk	6.02
30	104501 Roller, Front	2/pk	4.63
31	104502 Shaft, Front Roller Axle	2/pk	2.55
32	104503 Clamp, Rear Wheel	1 set	4.45
33	104495 Screw, Phillips, 4mm x 19mm, F/Powerhead	5/pk	3.48
34	104227 Sleeve, Hose, Air Duct	1 ea.	2.55
35	104230 Hose, Power Nozzle to Air Duct, Lower	1 ea.	5.88
36	104217 Belt, Drive, F/Brush Roll	1 ea.	5.79
37	104506 Motor, Power Nozzle with Crimps	1 ea.	75.34
38	104498 Grommet, Vibration, Power Nozzle Motor, Nitrile	2/pk	2.55
39	104224 Cover, Air Duct, Power Nozzle	1 ea.	4.79
40	104226 Board, Vacuum Operation Indicator	1 ea.	9.26
41	104507 Spring, Detent, Upright Lock	2/pk	3.48
42	105371 Screw, Phillips, 4.2mm x 19mm, F/Power Nozzle Motor	2/pk	2.32
43	105281 Carbon Brush Set for ProForce Motor	1 set	20.98
44	105760 Thermal Protector	1 ea.	9.37
	105755 Wire Harness Kit includes:	1 set	33.00

- A. Sensor, Bag, Full Indicator
- B. Harness, Wire, Main Power Supply
- C. Harness, Jumper, White
- D. Harness, Jumper, Red
- E. Harness, Wire, Power Nozzle
- F. Harness, Power Nozzle Switch

For shaded areas refer to page 44