


ProGuard® LI 3 Cordless

107489 ProGuard LI 3 Cordless
\$339


The ProGuard LI 3 Cordless Vacuum combines powerful vacuum performance with the cord-free convenience of 18-volt Lithium Ion power for quick cleanup. The ProGuard LI's lightweight design and narrow profile makes this vacuum easy to carry and easy to store.

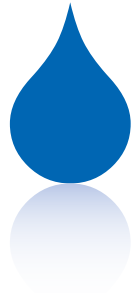

Specifications		Standard Configuration
Motor:	18 Volt, permanent magnet DC	2' to 7' Stretch Vacuum Hose
Airflow:	60 CFM	Crevice Tool
Static Lift:	38"	Dust Brush
Tank Size:	3 gallon/11.4 L	Claw Nozzle
Weight:	10.5 lbs./4.8 kg	Battery and Charger
Decibel:	72 dBA	Warranty
Fine Dust Cartridge Filter:	903 sq. in.	3 years on parts and labor
Battery Type:	Lithium Ion	1 year on vacuum motor, battery and charger
Approximate Run Time:	11 minutes	Limited lifetime on molded body parts
Approximate Charge Time:	30 minutes	

OPTIONAL ACCESSORY	RECOMMENDED ENVIRONMENTS:	RECOMMENDED APPLICATIONS:
107200 Battery Assembly \$104.95	<ul style="list-style-type: none"> • Education • Healthcare • Hospitality • Facility Service Providers 	<ul style="list-style-type: none"> • Small Spills • Flooding • Jobsite Cleanup • Day Porters • Spot Cleaning
107490 Charger 52.45		

PROGUARD LI 3 CORDLESS PARTS

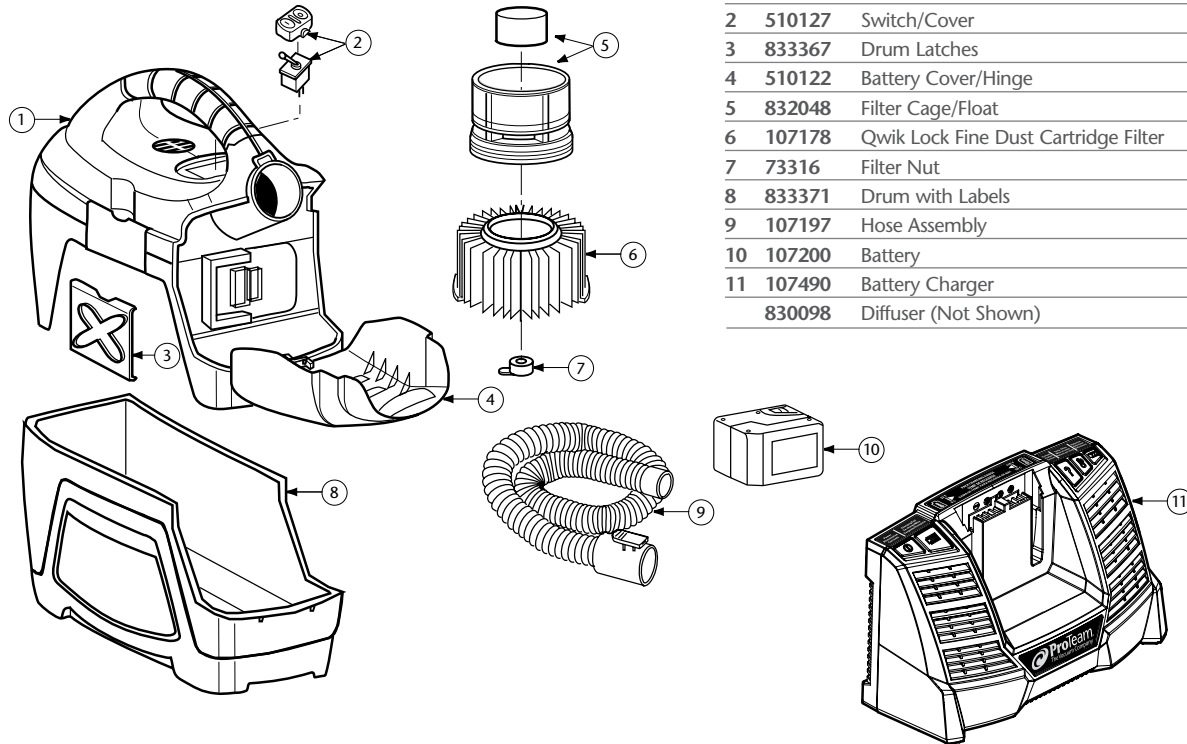

No.	Product Name	Qty	List Price
1	510121 Power Head	1 ea.	\$100.07
2	510127 Switch/Cover	1 ea.	1.84
3	833367 Drum Latches	2/pk	.84
4	510122 Battery Cover/Hinge	1 ea.	12.44
5	832048 Filter Cage/Float	1 ea.	1.84
6	107178 Qwik Lock Fine Dust Cartridge Filter	1 ea.	18.85
7	73316 Filter Nut	1 ea.	.16
8	833371 Drum with Labels	1 ea.	35.65
9	107197 Hose Assembly	1 ea.	28.51
10	107200 Battery	1 ea.	104.95
11	107490 Battery Charger	1 ea.	52.45
	830098 Diffuser (Not Shown)	1 ea.	4.99