

PROVAC[®] FS 6

The new triangular shape combined with ProTeam's innovative articulating FlexFit[®] harness have resulted in a vacuum that feels more like a part of your body. The load of the backpack is distributed to the natural center of gravity, so you have better balance no matter how you move.

The ProVac FS 6 is also adding versatility by having a NEW switch box connected to the waist belt that features a power nozzle connection. This will allow a power nozzle to be operated using one of the best backpack vacuums on the market. With long life and reliability, the power nozzle can take you to a new level of clean on high pile carpet.



NEW AND IMPROVED
switch box with power
nozzle connection

LESS FATIGUE

redesigned FlexFit harness
makes vacuum feel lighter
and more comfortable

STAY COOLER

open weave FlexFit
harness shields heat
during operation

FREEDOM OF MOVEMENT

articulating harness is
responsive to the motion of
the user's shoulders, back
and hips

WEIGHT DISTRIBUTION

innovative FlexFit harness distributes
weight evenly for lighter feel

NOTICEABLY QUIETER
only 65.8 dBA

REDUCED EMISSIONS

easy access post-motor HEPA media
filters capture and contain microscopic
particulates and carbon motor dust




JOIN THE MOVEMENT



	PROVAC® FS 6
Weight	11.6 lbs
Airflow	159 CFM
Static Lift	96 in
Power	1108 W
Amperage	9.5 A
Decibel	65.8 dBA
Capacity	6 qt. / 6.6 L
ProLevel™ Filtration w/ HEPA Media Filter	1054 sq. in total area
Warranty	3 years - parts, labor, motor Lifetime - molded body parts

PERFORMANCE SPECS BASED ON MOTOR SPECS

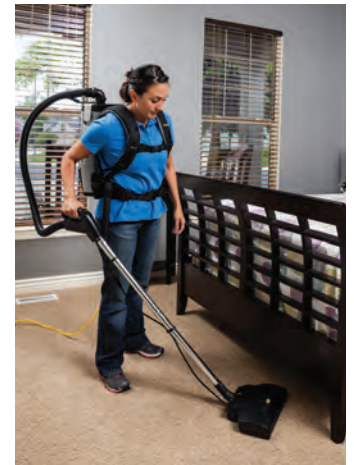

107461 ProVac FS 6 w/Commercial Power Nozzle Kit (103224) Includes:
 2-Piece Wand w/Cord Holder, Gas Pump Receptacle
 Dust Brush w/Swivel Joint
 Upholstery Tool w/Removable Brush
 Crevice Tool – 13"
 Power Nozzle
 Electrified Hose w/Gas Pump Handle, Elbow Cuff



proteam.emerson.com



866.888.2168 | customerservice.proteam@emerson.com

As a Proud Partner, ProTeam supports the American Lung Association's clean indoor air initiatives. The American Lung Association does not endorse product, device or service.

500090 1/17